

BA PROTECTION



BA protection BA BS DN6 - DN10

The BA BS backflow prevention device is specially designed for low flow rate applications. The BA BS, for example, is highly suitable for dentists' chairs and soap dispensers.


Standardisation

The BA BS is developed in accordance with EN 1717 and EN 12729.


Installation instructions

Install the BA BS according to EN1717.

Dimensions BA BS

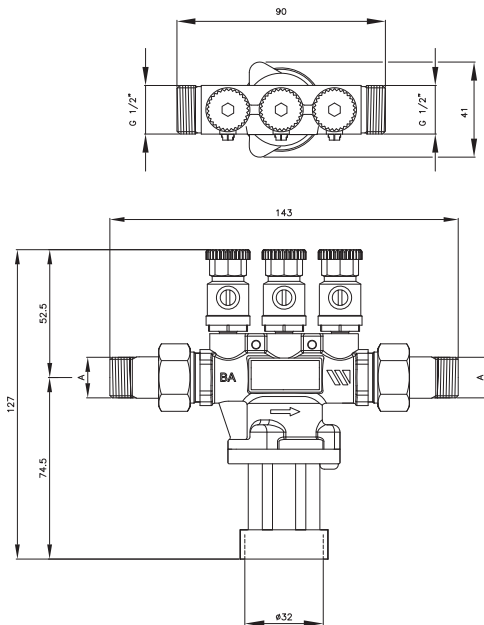

BA BS pressure loss curve

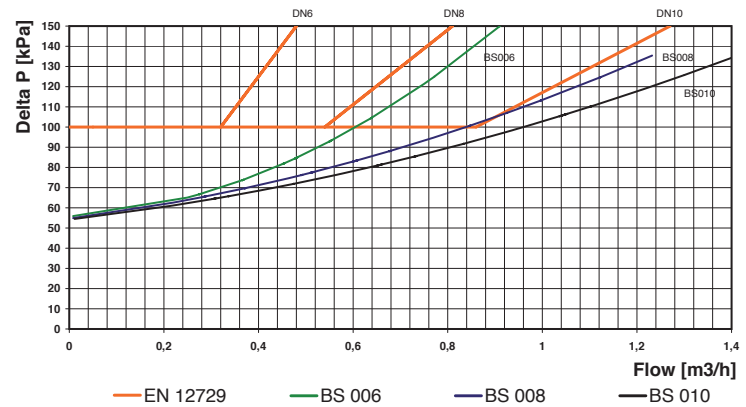

Article numbers BA BS

Type BS	DN	Device	Unit*
BA BS 006	6	405006010	405006311
BA BS 008	8	405008010	405008311
BA BS 010	10	405010010	405010311

* BA BS including funnel, filter and two valves

Material specifications BA BS

Body	brass
Relief valve body	plastic
Seal	rubber
Tundish	plastic
Connections	brass

Approvals (device) BA BS

Kiwa, WRAS, NF, Belgaqua, Sitac, DVGW, SVGW, SINTEF

Technical specifications BA BS

Max. system pressure	PN 10 (10 bar)
Nom. operating temperature	65 °C
Peak temperature	90 °C for 1 hour per day